


# Product datasheet

Specifications

## Data Center Expert Standard Appliance

AP9470

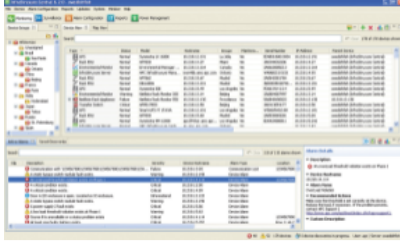

### Overview

<b>Presentation</b>	StruxureWare Data Center Expert Standard scales up to 2025 devices and 125 surveillance cameras.
<b>Lead time</b>	Usually Ships within 2 Weeks

### Main

<b>Number of rack unit</b>	1U
<b>Number of cables</b>	2
<b>Communication port protocol</b>	DNS HTTP HTTPS SMTP SMS SSL TCP/IP
<b>Provided equipment</b>	1 node surveillance license key 25-node license key CD with software Server appliance User manual Installation guide

### General

<b>Operating system</b>	Windows 7 Windows 8 Windows Vista Windows XP Windows XP Professional SP1 Windows XP Professional SP2
<b>Memory capacity</b>	2GB/250GB available for data storage

### Physical

<b>Colour</b>	Black
<b>Height</b>	4.4 cm
<b>Width</b>	48.3 cm
<b>Depth</b>	48.3 cm
<b>Net weight</b>	9.55 kg
<b>Mounting location</b>	Front
<b>Mounting preference</b>	No preference
<b>Mounting mode</b>	Rack-mounted

## Conformance

---

Product certifications TAA compliance

## Environmental

---

Ambient air temperature for operation 10...35 °C

---

Operating altitude 0...10000 ft

---

Relative humidity 5...90 %

---

Ambient air temperature for storage -35...60 °C

---

Storage altitude 0.00...9144.00 m

---

Storage Relative Humidity 5...95 %

## Communications & Management

---

Communication network type RJ45 10/100/1000 Base-T

## Packing Units

---

Unit Type of Package 1 PCE

---

Number of Units in Package 1 1

---

Package 1 Height 30.5 cm

---

Package 1 Width 88.9 cm

---

Package 1 Length 62.9 cm

---

Package 1 Weight 19.09 kg

## Offer Sustainability

---

EU RoHS Directive Under investigation

## Contractual warranty

---

Warranty 2 years repair or replace

## Recommended replacement(s)