


Product datasheet

Specifications

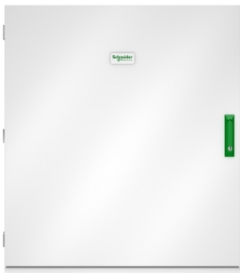

Galaxy VS Parallel Maintenance Bypass Panel for 2 UPSs, 60-120kW 400V Wallmount

GVSBP60K120H

Overview

Presentation	Maintenance bypass panel for complete isolation of two UPSs in parallel during service operations.
Lead Time	Usually Ships within 2 Weeks

Physical

Height	100 cm
Width	90 cm
Depth	28 cm
Net Weight	110 kg

Environmental

Ambient Air Temperature For Operation	0...40 °C
Ambient Air Temperature For Storage	-25...55 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	50 cm
Package 1 Width	100 cm
Package 1 Length	1200 cm
Package 1 Weight	120 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability




Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

[Learn more about Green Premium >](#)




Energy Efficient Take-back Transparency RoHS/REACH


Resource performance

 Energy Efficient Product

 Take-Back Program Available

Well-being performance

 Mercury Free

 Rohs Exemption Information [Yes](#)

Certifications & Standards

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Compliant with Exemptions

Environmental Disclosure [Product Environmental Profile](#)

Circularity Profile [End of Life Information](#)